



DryLin® R Linear - Product range

Square flange, twin pillow block - iglide® J liner

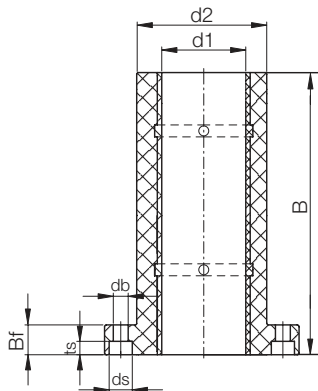

- Equipped with two JUM-02 liners for increased guiding length

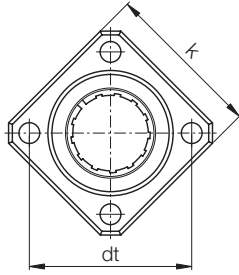

Order key

Type

Size

F J U M T - 0 2 - 1 0

Flange	iglide® J	Liner	Metric	Tandem	Round	Diameter
--------	-----------	-------	--------	--------	-------	----------

Technical Data

Part No.	Nominal size	d1-Tolerance ⁷⁸⁾ [mm]	Effective surface area [mm]	Weight [g]
FJZMT-02-08 ⁸⁵⁾	8	+0.032 +0.070	256	23,00
FJU MT-02-10	10	+0.030 +0.088	250	36,58
FJU MT-02-12	12	+0.030 +0.088	324	48,19
FJU MT-02-16	16	+0.030 +0.088	464	67,79
FJU MT-02-20	20	+0.030 +0.091	580	110,06
FJU MT-02-25	25	+0.030 +0.091	975	230,06
FJU MT-02-30	30	+0.030 +0.110	1,470	350,74
FJU MT-02-40	40	+0.030 +0.115	2,360	739,30
FJU MT-02-50	50	+0.030 +0.130	3,450	1249,30

Dimensions [mm]

Part No.	d1	d2	d3	dt	k	B	Bf	ts	db	ds
FJZMT-02-08 ⁸⁵⁾	8	16	32	24	25	45	8	3.1	3.5	6.0
FJU MT-02-10	10	19	39	29	30	52	9	4.1	4.5	7.5
FJU MT-02-12	12	22	42	32	32	57	9	4.1	4.5	7.5
FJU MT-02-16	16	26	46	36	35	70	9	4.1	4.5	7.5
FJU MT-02-20	20	32	54	43	42	80	11	5.1	5.5	9.0
FJU MT-02-25	25	40	62	51	50	112	11	5.1	5.5	9.0
FJU MT-02-30	30	47	76	62	60	123	14	6.1	6.6	11.0
FJU MT-02-40	40	62	98	80	75	151	18	8.1	9.0	14.0
FJU MT-02-50	50	75	112	94	88	192	18	8.1	9.0	14.0



⁷⁸⁾ According to igus® testing method ► Page 1096

⁸⁵⁾ FJZMT-01/02-08 are fitted with 2 pieces of JSM-0810-16

Please note: Installation instructions ► Page 1003